 


**PRECISION BRAND. 32 Piece Square Zinc Plated Steel Keystock Assortment**



Set Contents for 14680

Size (in)	Qty.
<b>12 in Zinc-Plated Square Keystock</b>	
3/16	6
1/4	6
5/16	6
3/8	6
7/16	4
1/2	4


**Features:**

- Used to provide driving torque between shafts and pulleys, gears, sprockets, etc.
- Oversized to ensure tight fits in keyways for positive, zero backlash power transmission
- Sizes marked on each piece
- ASTM A-108

**Finish:** Zinc-Plated  
**Material:** Steel

Item No.	Mfr. No.	Length (in)
<b>101460640</b>	14680	12

**PRECISION BRAND. Plated Steel Step Keystock**

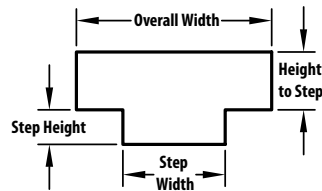

**Features:**

- Often referred to as offset keystock
- Used in the transmission of power from a shaft to a gear, sprocket, sheave, pulley, coupling, etc.
- ASTM A-108

**Finish:** Zinc-Plated  
**Length:** 12 in  
**Material:** Low Carbon Steel

**Type 1 - For Shafts**

Item No.	Mfr. No.	Overall Width (in)	Height to Step (in)	Step Width (in)	Step Height (in)
<b>101414318</b>	15801	3/16	3/32	1/8	1/16
<b>101414996</b>	15807	3/8	3/16	5/16	1/8
<b>101392707</b>	15808	3/8	3/16	5/16	5/32
<b>101394918</b>	15821	3/4	3/8	5/8	5/16
<b>101415391</b>	15827	1	1/2	7/8	7/16

**Type 2 - For Gears or Sprockets**

Item No.	Mfr. No.	Overall Width (in)	Height to Step (in)	Step Width (in)	Step Height (in)
<b>101439460</b>	15803	1/4	1/8	3/16	3/32
<b>101413960</b>	15802	1/4	3/32	3/16	3/32
<b>101413325</b>	15806	3/8	3/16	1/4	1/8
<b>101392625</b>	15805	3/8	1/8	1/4	1/8
<b>101391352</b>	15804	5/16	1/8	1/4	1/8
<b>101758421</b>	15809	7/16	5/32	3/8	3/16
<b>101412981</b>	15811	1/2	1/4	3/8	3/16
<b>101412912</b>	15810	1/2	3/16	3/8	3/16
<b>101810169</b>	15814	5/8	3/16	1/2	1/4
<b>101392708</b>	15815	5/8	5/16	1/2	1/4
<b>101415390</b>	15824	7/8	7/16	3/4	3/8

**PRECISION BRAND. Plated Rectangular Steel Keystock**

Used to provide driving torque between shafts and pulleys, gears, sprockets, etc.



**Features:**

- Most tolerances on dimensions are oversized to ensure tight fits in keyways for positive, zero backlash power transmission
- Used for new machinery, general maintenance and shop repairs
- Meets ASTM A-108

**Finish:** Zinc-Plated  
**Length:** 12 in  
**Material:** Carbon Steel

Item No.	Mfr. No.	Width (in)	Height (in)
<b>101392705</b>	15149	1/4	1/8
<b>101413958</b>	15199	1/4	3/16
<b>101414319</b>	15299	5/16	1/4
<b>101413235</b>	15249	3/8	3/16
<b>101392617</b>	15324	3/8	1/4
<b>101412907</b>	15374	3/8	5/16
<b>101391349</b>	15349	1/2	1/4
<b>101413320</b>	15399	1/2	5/16
<b>101413321</b>	15449	1/2	3/8
<b>101414991</b>	15514	1/2	7/16
<b>101393563</b>	15424	5/8	5/16
<b>101413234</b>	15474	5/8	3/8
<b>101412908</b>	15524	5/8	1/2
<b>101413957</b>	15499	3/4	3/8
<b>101391348</b>	15549	3/4	1/2
<b>101391347</b>	15574	3/4	5/8
<b>101414990</b>	15624	1	3/4



**Don't Forget...**

The Applied® Product Catalog is available as a FREE mobile app for the iPad®, iPhone®, iPod touch® and Android™ platforms – available from the [App Store<sup>SM</sup> on iTunes®](#) and the [Google Play™ store!](#) This convenient app gives you complete access to the entire catalog and is linked directly to [Applied.com](#) for easy ordering. Download today!

